

Star Grips • DIN 6336 plastic  
EH 24670.



Product Description

Material


Bushing

- Brass
- Steel, zinc-plated by galvanization
- Stainless steel A2

Handle

- DIN 7708 - thermosetting plastic (PF 31), black similar to RAL 9005


Drawing

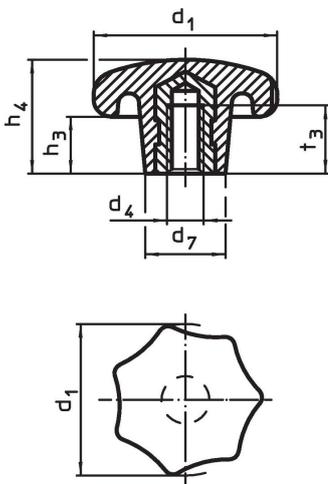

Order information

Dimensions						max. [°C]	[g]	Art. No.
d <sub>1</sub>	d <sub>4</sub>	d <sub>7</sub>	h <sub>3</sub>	h <sub>4</sub>	t <sub>3</sub>			
<b>with threaded bushing, form K, Brass</b>								
20	M 4	10	7	13	6.5	110	3.4	<a href="#">24670.0220</a>
<b>with threaded bushing, form K, Steel</b>								
25	M 5	12	8	16	9.5	110	7.4	<a href="#">24670.0225</a>
32	M 6	14	10	20	12.0	110	13.0	<a href="#">24670.0232</a>
40	M 8	18	13	25	14.0	110	20.0	<a href="#">24670.0240</a>
50	M10	22	17	32	18.0	110	40.0	<a href="#">24670.0250</a>
63	M12	26	21	40	22.0	110	83.0	<a href="#">24670.0263</a>
80	M16	35	25	50	30.0	110	161.0	<a href="#">24670.0280</a>
<b>with threaded bushing, form K, Stainless steel</b>								
25	M 5	12	8	16	9.5	110	7.4	<a href="#">24670.1225</a>
32	M 6	14	10	20	12.0	110	13.0	<a href="#">24670.1232</a>
40	M 8	18	13	25	14.0	110	20.0	<a href="#">24670.1240</a>
50	M10	22	17	32	18.0	110	40.0	<a href="#">24670.1250</a>
63	M12	26	21	40	22.0	110	83.0	<a href="#">24670.1263</a>
80	M16	35	25	50	30.0	110	161.0	<a href="#">24670.1280</a>

## Application example

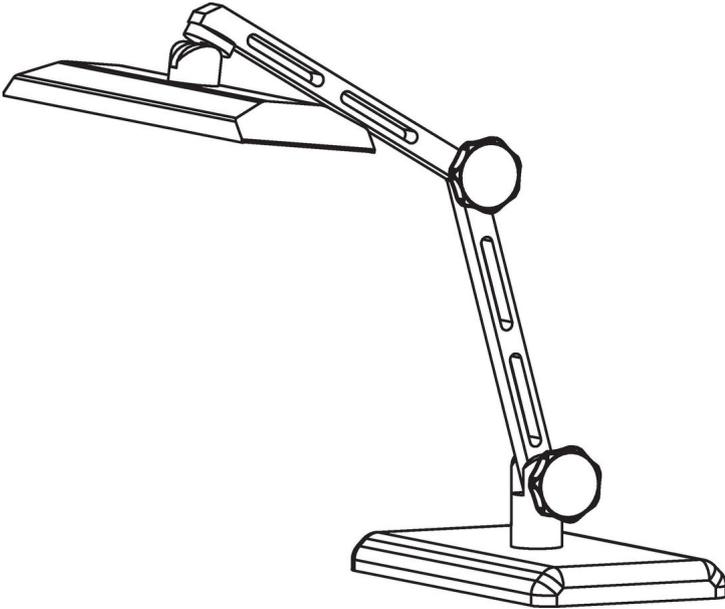

## Compliance

### RoHS compliant

Compliant according to Directive 2011/65/EU and Directive 2015/863.

### Does not contain SVHC substances

No SVHC substances with more than 0.1% w/w contained - SVHC list [REACH] as of 23.01.2024.

### Does not contain Proposition 65 substances

No Proposition 65 substances included.

<https://www.P65Warnings.ca.gov/>

### Free from Conflict Minerals

This product does not contain any substances designated as "conflict minerals" such as tantalum, tin, gold or tungsten from the Democratic Republic of Congo or adjacent countries.