

Mâner deget EH 24520.



Descrierea produsului

Material

- Oțel, brunat
- Oțel inoxidabil 1.4305, sablare mată

Desen

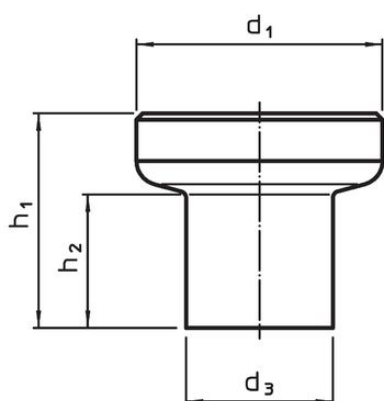


Figura 1


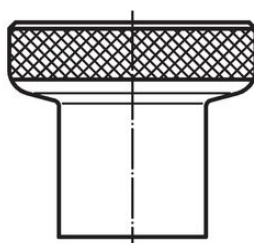


Figura 2

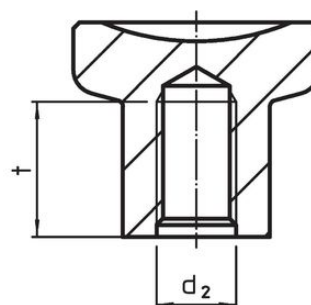


Informații comandă

d ₁	d ₂	Dimensiuni				t min.		Ref. Nr.
		d ₃	h ₁	h ₂	[mm]			
[g]								
fără striății – figura 1, Oțel								
21	M 4	12,5	18,0	10,5	10	26	24520.0002	
21	M 5	12,5	18,0	10,5	10	25	24520.0003	
25	M 6	14,5	22,5	14,0	12	42	24520.0005	
25	M 8	14,5	22,5	14,0	12	38	24520.0006	
31	M 8	18,5	27,0	17,0	15	75	24520.0008	
31	M10	18,5	27,0	17,0	17	70	24520.0009	
cu striății – figura 2, Oțel								
21	M 4	12,5	18,0	10,5	10	26	24520.0022	
21	M 5	12,5	18,0	10,5	10	25	24520.0023	
25	M 6	14,5	22,5	14,0	12	42	24520.0025	
25	M 8	14,5	22,5	14,0	12	39	24520.0026	
31	M 8	18,5	27,0	17,0	15	75	24520.0028	
31	M10	18,5	27,0	17,0	17	70	24520.0029	
fără striății – figura 1, Oțel inoxidabil								
21	M 4	12,5	18,0	10,5	10	26	24520.0102	
21	M 5	12,5	18,0	10,5	10	25	24520.0103	
25	M 6	14,5	22,5	14,0	12	42	24520.0105	
25	M 8	14,5	22,5	14,0	12	38	24520.0106	
31	M 8	18,5	27,0	17,0	15	75	24520.0108	
31	M10	18,5	27,0	17,0	17	70	24520.0109	

Dimensiuni							Ref. Nr.
d ₁	d ₂	d ₃	h ₁	h ₂	t min.		
[mm]							
cu striății – figura 2, Oțel inoxidabil							
21	M 4	12,5	18,0	10,5	10	26	24520.0122
21	M 5	12,5	18,0	10,5	10	25	24520.0123
25	M 6	14,5	22,5	14,0	12	42	24520.0125
25	M 8	14,5	22,5	14,0	12	39	24520.0126
31	M 8	18,5	27,0	17,0	15	75	24520.0128
31	M10	18,5	27,0	17,0	17	70	24520.0129

Exemplu de aplicație

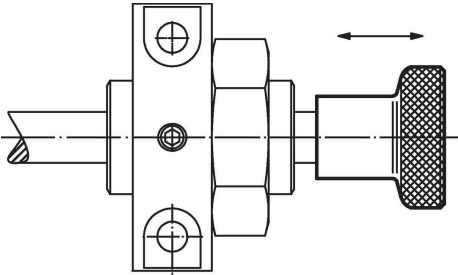

Reclamație

Pentru detalii suplimentare despre conformitate, vă rugăm să selectați codul produsului dorit.