

# Knöpfe

## EH 24520.



### Produktbeschreibung

#### Werkstoff

- Stahl, brüniert
- Rostfreier Stahl 1.4305, matt gestrahlt

### Maßzeichnung

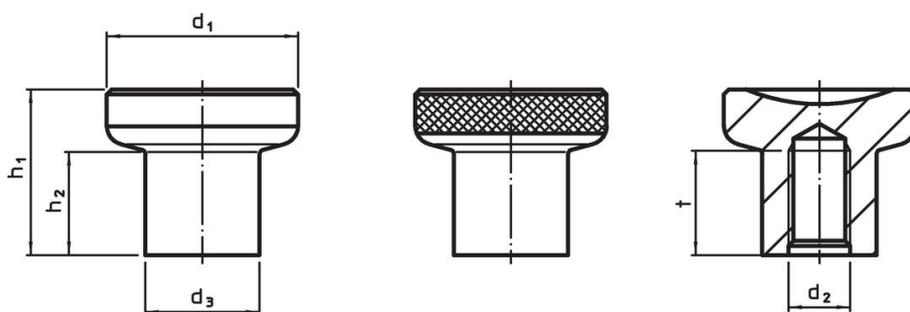


Bild 1


Bild 2

### Bestellinformationen

d <sub>1</sub>	d <sub>2</sub>	d <sub>3</sub>	Abmessungen			t min.	[g]	Art.-Nr.
			[mm]					
<b>ohne Rändel – Bild 1, Stahl</b>								
21	M 4	12,5	18,0	10,5	10	26	24520.0002	
21	M 5	12,5	18,0	10,5	10	25	24520.0003	
25	M 6	14,5	22,5	14,0	12	42	24520.0005	
25	M 8	14,5	22,5	14,0	12	38	24520.0006	
31	M 8	18,5	27,0	17,0	15	75	24520.0008	
31	M10	18,5	27,0	17,0	17	70	24520.0009	
<b>mit Rändel – Bild 2, Stahl</b>								
21	M 4	12,5	18,0	10,5	10	26	24520.0022	
21	M 5	12,5	18,0	10,5	10	25	24520.0023	
25	M 6	14,5	22,5	14,0	12	42	24520.0025	
25	M 8	14,5	22,5	14,0	12	39	24520.0026	
31	M 8	18,5	27,0	17,0	15	75	24520.0028	
31	M10	18,5	27,0	17,0	17	70	24520.0029	
<b>ohne Rändel – Bild 1, Rostfreier Stahl</b>								
21	M 4	12,5	18,0	10,5	10	26	24520.0102	
21	M 5	12,5	18,0	10,5	10	25	24520.0103	
25	M 6	14,5	22,5	14,0	12	42	24520.0105	
25	M 8	14,5	22,5	14,0	12	38	24520.0106	
31	M 8	18,5	27,0	17,0	15	75	24520.0108	
31	M10	18,5	27,0	17,0	17	70	24520.0109	

d <sub>1</sub>	d <sub>2</sub>	Abmessungen				t min.	 [g]	Art.-Nr.
		d <sub>3</sub>	h <sub>1</sub>	h <sub>2</sub>	[mm]			
<b>mit Rändel – Bild 2, Rostfreier Stahl</b>								
21	M 4	12,5	18,0	10,5	10	26	<a href="#">24520.0122</a>	
21	M 5	12,5	18,0	10,5	10	25	<a href="#">24520.0123</a>	
25	M 6	14,5	22,5	14,0	12	42	<a href="#">24520.0125</a>	
25	M 8	14,5	22,5	14,0	12	39	<a href="#">24520.0126</a>	
31	M 8	18,5	27,0	17,0	15	75	<a href="#">24520.0128</a>	
31	M10	18,5	27,0	17,0	17	70	<a href="#">24520.0129</a>	

### Anwendungsbeispiel

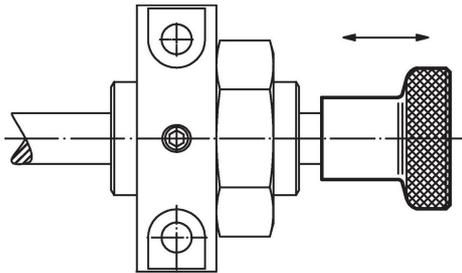

### Compliance

Für detaillierte Compliance Informationen wählen Sie bitte die gewünschte Artikelnummer.