

支撑脚  
EH 22593.



产品描述

支撑脚是万用的就像可调整脚一样。  
板件被锁在螺纹销和螺母上，藉由一个不锈钢锁附螺丝，同时胶水沾黏。

材质

- 螺纹销
- 钢，镀锌，钝化
  - 不锈钢 1.4305

- 螺帽
- 钢，镀锌，钝化
  - 不锈钢 1.4305

- 固定螺帽
- 钢，镀锌，钝化，ISO 4032
  - 不锈钢 A2, ISO 4032




- 脚座
- 钢，镀锌，钝化
  - 不锈钢 1.4301，振动研磨

更多信息

更多产品

- 支撑脚，防滑保护

图面

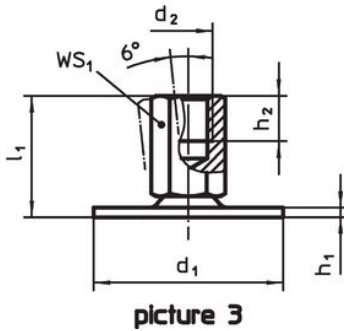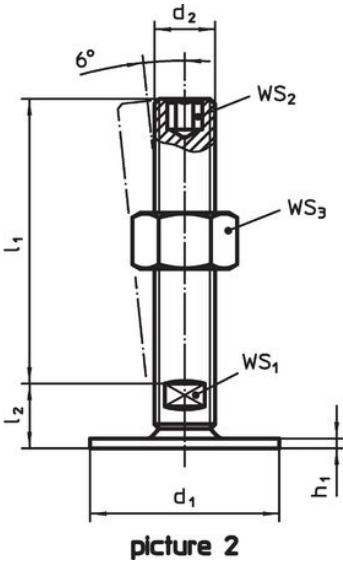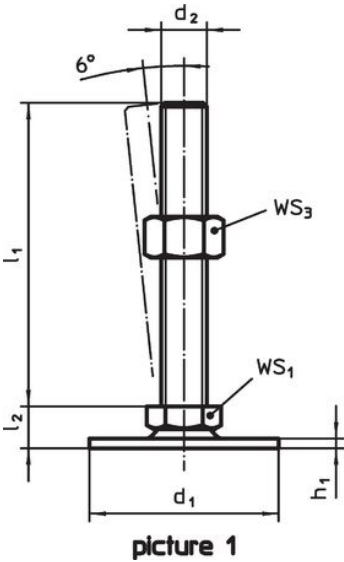

订单信息

| 尺寸             |                |                |                |                |                | WS <sub>1</sub> | WS <sub>2</sub> | WS <sub>3</sub> |  | 品号         |
|----------------|----------------|----------------|----------------|----------------|----------------|-----------------|-----------------|-----------------|---------------------------------------------------------------------------------------|------------|
| d <sub>1</sub> | d <sub>2</sub> | l <sub>1</sub> | h <sub>1</sub> | h <sub>2</sub> | l <sub>2</sub> | [mm]            | [mm]            | [mm]            | [g]                                                                                   |            |
| 有螺丝 – 相片 1, 钢  |                |                |                |                |                |                 |                 |                 |                                                                                       |            |
| 40             | M 8            | 40             | 2,0            | –              | 11             | 17              | –               | 13              | 45                                                                                    | 22593.0005 |
| 40             | M 8            | 50             | 2,0            | –              | 11             | 17              | –               | 13              | 48                                                                                    | 22593.0010 |
| 40             | M 8            | 63             | 2,0            | –              | 11             | 17              | –               | 13              | 48                                                                                    | 22593.0015 |
| 40             | M10            | 50             | 2,0            | –              | 11             | 17              | –               | 16              | 62                                                                                    | 22593.0020 |
| 40             | M10            | 60             | 2,0            | –              | 11             | 17              | –               | 16              | 69                                                                                    | 22593.0025 |
| 40             | M10            | 80             | 2,0            | –              | 11             | 17              | –               | 16              | 76                                                                                    | 22593.0030 |
| 40             | M10            | 100            | 2,0            | –              | 11             | 17              | –               | 16              | 87                                                                                    | 22593.0035 |
| 40             | M12            | 60             | 2,0            | –              | 11             | 17              | –               | 18              | 85                                                                                    | 22593.0040 |
| 40             | M12            | 80             | 2,0            | –              | 11             | 17              | –               | 18              | 98                                                                                    | 22593.0045 |
| 40             | M12            | 100            | 2,0            | –              | 11             | 17              | –               | 18              | 113                                                                                   | 22593.0050 |
| 40             | M12            | 125            | 2,0            | –              | 11             | 17              | –               | 18              | 132                                                                                   | 22593.0055 |
| 50             | M 8            | 40             | 2,5            | –              | 11             | 17              | –               | 13              | 62                                                                                    | 22593.0060 |

| 尺寸             |                |                |                |                |                | WS <sub>1</sub> | WS <sub>2</sub> | WS <sub>3</sub> |  | 品号                         |
|----------------|----------------|----------------|----------------|----------------|----------------|-----------------|-----------------|-----------------|-------------------------------------------------------------------------------------|----------------------------|
| d <sub>1</sub> | d <sub>2</sub> | l <sub>1</sub> | h <sub>1</sub> | h <sub>2</sub> | l <sub>2</sub> |                 |                 |                 |                                                                                     |                            |
| [mm]           |                |                |                |                |                | [mm]            | [mm]            | [mm]            | [g]                                                                                 |                            |
| 50             | M 8            | 50             | 2,5            | –              | 11             | 17              | –               | 13              | 68                                                                                  | <a href="#">22593.0065</a> |
| 50             | M 8            | 63             | 2,5            | –              | 11             | 17              | –               | 13              | 70                                                                                  | <a href="#">22593.0070</a> |
| 50             | M10            | 50             | 2,5            | –              | 11             | 17              | –               | 16              | 80                                                                                  | <a href="#">22593.0075</a> |
| 50             | M10            | 60             | 2,5            | –              | 11             | 17              | –               | 16              | 86                                                                                  | <a href="#">22593.0080</a> |
| 50             | M10            | 80             | 2,5            | –              | 11             | 17              | –               | 16              | 95                                                                                  | <a href="#">22593.0085</a> |
| 50             | M10            | 100            | 2,5            | –              | 11             | 17              | –               | 16              | 106                                                                                 | <a href="#">22593.0090</a> |
| 50             | M12            | 60             | 2,5            | –              | 11             | 17              | –               | 18              | 102                                                                                 | <a href="#">22593.0095</a> |
| 50             | M12            | 80             | 2,5            | –              | 11             | 17              | –               | 18              | 117                                                                                 | <a href="#">22593.0100</a> |
| 50             | M12            | 100            | 2,5            | –              | 11             | 17              | –               | 18              | 132                                                                                 | <a href="#">22593.0105</a> |
| 50             | M12            | 125            | 2,5            | –              | 11             | 17              | –               | 18              | 150                                                                                 | <a href="#">22593.0110</a> |
| 60             | M 8            | 40             | 2,5            | –              | 11             | 17              | –               | 13              | 81                                                                                  | <a href="#">22593.0115</a> |
| 60             | M 8            | 50             | 2,5            | –              | 11             | 17              | –               | 13              | 83                                                                                  | <a href="#">22593.0120</a> |
| 60             | M 8            | 63             | 2,5            | –              | 11             | 17              | –               | 13              | 87                                                                                  | <a href="#">22593.0125</a> |
| 60             | M10            | 50             | 2,5            | –              | 11             | 17              | –               | 16              | 97                                                                                  | <a href="#">22593.0130</a> |
| 60             | M10            | 60             | 2,5            | –              | 11             | 17              | –               | 16              | 103                                                                                 | <a href="#">22593.0135</a> |
| 60             | M10            | 80             | 2,5            | –              | 11             | 17              | –               | 16              | 111                                                                                 | <a href="#">22593.0140</a> |
| 60             | M10            | 100            | 2,5            | –              | 11             | 17              | –               | 16              | 122                                                                                 | <a href="#">22593.0145</a> |
| 60             | M12            | 60             | 2,5            | –              | 11             | 17              | –               | 18              | 120                                                                                 | <a href="#">22593.0150</a> |
| 60             | M12            | 80             | 2,5            | –              | 11             | 17              | –               | 18              | 134                                                                                 | <a href="#">22593.0155</a> |
| 60             | M12            | 100            | 2,5            | –              | 11             | 17              | –               | 18              | 150                                                                                 | <a href="#">22593.0160</a> |
| 60             | M12            | 125            | 2,5            | –              | 11             | 17              | –               | 18              | 167                                                                                 | <a href="#">22593.0165</a> |
| 80             | M 8            | 40             | 3,0            | –              | 12             | 17              | –               | 13              | 144                                                                                 | <a href="#">22593.0170</a> |
| 80             | M 8            | 50             | 3,0            | –              | 12             | 17              | –               | 13              | 148                                                                                 | <a href="#">22593.0175</a> |
| 80             | M 8            | 63             | 3,0            | –              | 12             | 17              | –               | 13              | 152                                                                                 | <a href="#">22593.0180</a> |
| 80             | M10            | 50             | 3,0            | –              | 12             | 17              | –               | 16              | 163                                                                                 | <a href="#">22593.0185</a> |
| 80             | M10            | 60             | 3,0            | –              | 12             | 17              | –               | 16              | 167                                                                                 | <a href="#">22593.0190</a> |
| 80             | M10            | 80             | 3,0            | –              | 12             | 17              | –               | 16              | 176                                                                                 | <a href="#">22593.0195</a> |
| 80             | M10            | 100            | 3,0            | –              | 12             | 17              | –               | 16              | 187                                                                                 | <a href="#">22593.0200</a> |
| 80             | M12            | 60             | 3,0            | –              | 12             | 17              | –               | 18              | 186                                                                                 | <a href="#">22593.0205</a> |
| 80             | M12            | 80             | 3,0            | –              | 12             | 17              | –               | 18              | 199                                                                                 | <a href="#">22593.0210</a> |
| 80             | M12            | 100            | 3,0            | –              | 12             | 17              | –               | 18              | 218                                                                                 | <a href="#">22593.0215</a> |
| 80             | M12            | 125            | 3,0            | –              | 12             | 17              | –               | 18              | 231                                                                                 | <a href="#">22593.0220</a> |
| 有螺丝 – 相片 2, 钢  |                |                |                |                |                |                 |                 |                 |                                                                                     |                            |
| 40             | M16            | 75             | 2,0            | –              | 17             | 12              | 8               | 24              | 154                                                                                 | <a href="#">22593.0605</a> |
| 40             | M16            | 100            | 2,0            | –              | 17             | 12              | 8               | 24              | 183                                                                                 | <a href="#">22593.0610</a> |
| 40             | M16            | 125            | 2,0            | –              | 17             | 12              | 8               | 24              | 217                                                                                 | <a href="#">22593.0615</a> |
| 40             | M16            | 150            | 2,0            | –              | 17             | 12              | 8               | 24              | 252                                                                                 | <a href="#">22593.0620</a> |
| 40             | M16            | 200            | 2,0            | –              | 17             | 12              | 8               | 24              | 315                                                                                 | <a href="#">22593.0625</a> |
| 50             | M16            | 75             | 2,5            | –              | 17             | 12              | 8               | 24              | 172                                                                                 | <a href="#">22593.0630</a> |
| 50             | M16            | 100            | 2,5            | –              | 17             | 12              | 8               | 24              | 205                                                                                 | <a href="#">22593.0635</a> |
| 50             | M16            | 125            | 2,5            | –              | 17             | 12              | 8               | 24              | 236                                                                                 | <a href="#">22593.0640</a> |
| 50             | M16            | 150            | 2,5            | –              | 17             | 12              | 8               | 24              | 270                                                                                 | <a href="#">22593.0645</a> |
| 50             | M16            | 200            | 2,5            | –              | 17             | 12              | 8               | 24              | 335                                                                                 | <a href="#">22593.0650</a> |
| 60             | M16            | 75             | 2,5            | –              | 17             | 12              | 8               | 24              | 187                                                                                 | <a href="#">22593.0655</a> |
| 60             | M16            | 100            | 2,5            | –              | 17             | 12              | 8               | 24              | 221                                                                                 | <a href="#">22593.0660</a> |
| 60             | M16            | 125            | 2,5            | –              | 17             | 12              | 8               | 24              | 252                                                                                 | <a href="#">22593.0665</a> |
| 60             | M16            | 150            | 2,5            | –              | 17             | 12              | 8               | 24              | 288                                                                                 | <a href="#">22593.0670</a> |
| 60             | M16            | 200            | 2,5            | –              | 17             | 12              | 8               | 24              | 352                                                                                 | <a href="#">22593.0675</a> |
| 80             | M16            | 75             | 3,0            | –              | 18             | 12              | 8               | 24              | 251                                                                                 | <a href="#">22593.0680</a> |
| 80             | M16            | 100            | 3,0            | –              | 18             | 12              | 8               | 24              | 285                                                                                 | <a href="#">22593.0685</a> |
| 80             | M16            | 125            | 3,0            | –              | 18             | 12              | 8               | 24              | 317                                                                                 | <a href="#">22593.0690</a> |
| 80             | M16            | 150            | 3,0            | –              | 18             | 12              | 8               | 24              | 349                                                                                 | <a href="#">22593.0695</a> |
| 80             | M16            | 200            | 3,0            | –              | 18             | 12              | 8               | 24              | 414                                                                                 | <a href="#">22593.0700</a> |
| 80             | M20            | 75             | 3,0            | –              | 19             | 15              | 10              | 30              | 340                                                                                 | <a href="#">22593.0705</a> |
| 80             | M20            | 100            | 3,0            | –              | 19             | 15              | 10              | 30              | 393                                                                                 | <a href="#">22593.0710</a> |
| 80             | M20            | 125            | 3,0            | –              | 19             | 15              | 10              | 30              | 441                                                                                 | <a href="#">22593.0715</a> |
| 80             | M20            | 150            | 3,0            | –              | 19             | 15              | 10              | 30              | 494                                                                                 | <a href="#">22593.0720</a> |
| 80             | M20            | 200            | 3,0            | –              | 19             | 15              | 10              | 30              | 600                                                                                 | <a href="#">22593.0725</a> |
| 80             | M24            | 100            | 3,0            | –              | 22             | 19              | 12              | 36              | 537                                                                                 | <a href="#">22593.0730</a> |
| 80             | M24            | 125            | 3,0            | –              | 22             | 19              | 12              | 36              | 610                                                                                 | <a href="#">22593.0735</a> |
| 80             | M24            | 150            | 3,0            | –              | 22             | 19              | 12              | 36              | 681                                                                                 | <a href="#">22593.0740</a> |
| 80             | M24            | 200            | 3,0            | –              | 22             | 19              | 12              | 36              | 829                                                                                 | <a href="#">22593.0745</a> |

| 尺寸              |                |                |                |                |                | WS <sub>1</sub> | WS <sub>2</sub> | WS <sub>3</sub> |  | 品号                         |
|-----------------|----------------|----------------|----------------|----------------|----------------|-----------------|-----------------|-----------------|-------------------------------------------------------------------------------------|----------------------------|
| d <sub>1</sub>  | d <sub>2</sub> | l <sub>1</sub> | h <sub>1</sub> | h <sub>2</sub> | l <sub>2</sub> |                 |                 |                 |                                                                                     |                            |
| 有母牙 – 相片 3, 钢   |                |                |                |                |                |                 |                 |                 |                                                                                     |                            |
| 40              | M 8            | 25             | 2,0            | 8              | –              | 14              | –               | –               | 41                                                                                  | <a href="#">22593.1005</a> |
| 40              | M10            | 28             | 2,0            | 10             | –              | 14              | –               | –               | 40                                                                                  | <a href="#">22593.1010</a> |
| 40              | M12            | 31             | 2,0            | 12             | –              | 17              | –               | –               | 57                                                                                  | <a href="#">22593.1015</a> |
| 40              | M16            | 37             | 2,0            | 16             | –              | 22              | –               | –               | 93                                                                                  | <a href="#">22593.1020</a> |
| 50              | M 8            | 25             | 2,5            | 8              | –              | 14              | –               | –               | 59                                                                                  | <a href="#">22593.1025</a> |
| 50              | M10            | 28             | 2,5            | 10             | –              | 14              | –               | –               | 58                                                                                  | <a href="#">22593.1030</a> |
| 50              | M12            | 32             | 2,5            | 12             | –              | 17              | –               | –               | 76                                                                                  | <a href="#">22593.1035</a> |
| 50              | M16            | 37             | 2,5            | 16             | –              | 22              | –               | –               | 112                                                                                 | <a href="#">22593.1040</a> |
| 60              | M 8            | 25             | 2,5            | 8              | –              | 14              | –               | –               | 76                                                                                  | <a href="#">22593.1045</a> |
| 60              | M10            | 28             | 2,5            | 10             | –              | 14              | –               | –               | 77                                                                                  | <a href="#">22593.1050</a> |
| 60              | M12            | 32             | 2,5            | 12             | –              | 17              | –               | –               | 92                                                                                  | <a href="#">22593.1055</a> |
| 60              | M16            | 37             | 2,5            | 16             | –              | 22              | –               | –               | 127                                                                                 | <a href="#">22593.1060</a> |
| 80              | M 8            | 26             | 3,0            | 8              | –              | 14              | –               | –               | 140                                                                                 | <a href="#">22593.1065</a> |
| 80              | M10            | 29             | 3,0            | 10             | –              | 14              | –               | –               | 144                                                                                 | <a href="#">22593.1070</a> |
| 80              | M12            | 32             | 3,0            | 12             | –              | 17              | –               | –               | 160                                                                                 | <a href="#">22593.1075</a> |
| 80              | M16            | 38             | 3,0            | 16             | –              | 22              | –               | –               | 195                                                                                 | <a href="#">22593.1080</a> |
| 80              | M20            | 45             | 3,0            | 20             | –              | 27              | –               | –               | 256                                                                                 | <a href="#">22593.1085</a> |
| 有螺丝 – 相片 1, 不锈钢 |                |                |                |                |                |                 |                 |                 |                                                                                     |                            |
| 40              | M 8            | 40             | 2,0            | –              | 11             | 17              | –               | 13              | 45                                                                                  | <a href="#">22593.1505</a> |
| 40              | M 8            | 50             | 2,0            | –              | 11             | 17              | –               | 13              | 48                                                                                  | <a href="#">22593.1510</a> |
| 40              | M 8            | 63             | 2,0            | –              | 11             | 17              | –               | 13              | 48                                                                                  | <a href="#">22593.1515</a> |
| 40              | M10            | 50             | 2,0            | –              | 11             | 17              | –               | 16              | 62                                                                                  | <a href="#">22593.1520</a> |
| 40              | M10            | 60             | 2,0            | –              | 11             | 17              | –               | 16              | 69                                                                                  | <a href="#">22593.1525</a> |
| 40              | M10            | 80             | 2,0            | –              | 11             | 17              | –               | 16              | 76                                                                                  | <a href="#">22593.1530</a> |
| 40              | M10            | 100            | 2,0            | –              | 11             | 17              | –               | 16              | 87                                                                                  | <a href="#">22593.1535</a> |
| 40              | M12            | 60             | 2,0            | –              | 11             | 17              | –               | 18              | 85                                                                                  | <a href="#">22593.1540</a> |
| 40              | M12            | 80             | 2,0            | –              | 11             | 17              | –               | 18              | 98                                                                                  | <a href="#">22593.1545</a> |
| 40              | M12            | 100            | 2,0            | –              | 11             | 17              | –               | 18              | 113                                                                                 | <a href="#">22593.1550</a> |
| 40              | M12            | 125            | 2,0            | –              | 11             | 17              | –               | 18              | 132                                                                                 | <a href="#">22593.1555</a> |
| 50              | M 8            | 40             | 2,5            | –              | 11             | 17              | –               | 13              | 62                                                                                  | <a href="#">22593.1560</a> |
| 50              | M 8            | 50             | 2,5            | –              | 11             | 17              | –               | 13              | 68                                                                                  | <a href="#">22593.1565</a> |
| 50              | M 8            | 63             | 2,5            | –              | 11             | 17              | –               | 13              | 70                                                                                  | <a href="#">22593.1570</a> |
| 50              | M10            | 50             | 2,5            | –              | 11             | 17              | –               | 16              | 80                                                                                  | <a href="#">22593.1575</a> |
| 50              | M10            | 60             | 2,5            | –              | 11             | 17              | –               | 16              | 86                                                                                  | <a href="#">22593.1580</a> |
| 50              | M10            | 80             | 2,5            | –              | 11             | 17              | –               | 16              | 95                                                                                  | <a href="#">22593.1585</a> |
| 50              | M10            | 100            | 2,5            | –              | 11             | 17              | –               | 16              | 106                                                                                 | <a href="#">22593.1590</a> |
| 50              | M12            | 60             | 2,5            | –              | 11             | 17              | –               | 18              | 102                                                                                 | <a href="#">22593.1595</a> |
| 50              | M12            | 80             | 2,5            | –              | 11             | 17              | –               | 18              | 117                                                                                 | <a href="#">22593.1600</a> |
| 50              | M12            | 100            | 2,5            | –              | 11             | 17              | –               | 18              | 132                                                                                 | <a href="#">22593.1605</a> |
| 50              | M12            | 125            | 2,5            | –              | 11             | 17              | –               | 18              | 150                                                                                 | <a href="#">22593.1610</a> |
| 60              | M 8            | 40             | 2,5            | –              | 11             | 17              | –               | 13              | 81                                                                                  | <a href="#">22593.1615</a> |
| 60              | M 8            | 50             | 2,5            | –              | 11             | 17              | –               | 13              | 83                                                                                  | <a href="#">22593.1620</a> |
| 60              | M 8            | 63             | 2,5            | –              | 11             | 17              | –               | 13              | 87                                                                                  | <a href="#">22593.1625</a> |
| 60              | M10            | 50             | 2,5            | –              | 11             | 17              | –               | 16              | 97                                                                                  | <a href="#">22593.1630</a> |
| 60              | M10            | 60             | 2,5            | –              | 11             | 17              | –               | 16              | 103                                                                                 | <a href="#">22593.1635</a> |
| 60              | M10            | 80             | 2,5            | –              | 11             | 17              | –               | 16              | 111                                                                                 | <a href="#">22593.1640</a> |
| 60              | M10            | 100            | 2,5            | –              | 11             | 17              | –               | 16              | 122                                                                                 | <a href="#">22593.1645</a> |
| 60              | M12            | 60             | 2,5            | –              | 11             | 17              | –               | 18              | 120                                                                                 | <a href="#">22593.1650</a> |
| 60              | M12            | 80             | 2,5            | –              | 11             | 17              | –               | 18              | 134                                                                                 | <a href="#">22593.1655</a> |
| 60              | M12            | 100            | 2,5            | –              | 11             | 17              | –               | 18              | 150                                                                                 | <a href="#">22593.1660</a> |
| 60              | M12            | 125            | 2,5            | –              | 11             | 17              | –               | 18              | 167                                                                                 | <a href="#">22593.1665</a> |
| 80              | M 8            | 40             | 3,0            | –              | 12             | 17              | –               | 13              | 144                                                                                 | <a href="#">22593.1670</a> |
| 80              | M 8            | 50             | 3,0            | –              | 12             | 17              | –               | 13              | 148                                                                                 | <a href="#">22593.1675</a> |
| 80              | M 8            | 63             | 3,0            | –              | 12             | 17              | –               | 13              | 152                                                                                 | <a href="#">22593.1680</a> |
| 80              | M10            | 50             | 3,0            | –              | 12             | 17              | –               | 16              | 163                                                                                 | <a href="#">22593.1685</a> |
| 80              | M10            | 60             | 3,0            | –              | 12             | 17              | –               | 16              | 167                                                                                 | <a href="#">22593.1690</a> |
| 80              | M10            | 80             | 3,0            | –              | 12             | 17              | –               | 16              | 176                                                                                 | <a href="#">22593.1695</a> |
| 80              | M10            | 100            | 3,0            | –              | 12             | 17              | –               | 16              | 187                                                                                 | <a href="#">22593.1700</a> |

| 尺寸              |                |                |                |                |                | WS <sub>1</sub> | WS <sub>2</sub> | WS <sub>3</sub> |  | 品号                         |
|-----------------|----------------|----------------|----------------|----------------|----------------|-----------------|-----------------|-----------------|-------------------------------------------------------------------------------------|----------------------------|
| d <sub>1</sub>  | d <sub>2</sub> | l <sub>1</sub> | h <sub>1</sub> | h <sub>2</sub> | l <sub>2</sub> | [mm]            | [mm]            | [mm]            | [g]                                                                                 |                            |
| [mm]            |                |                |                |                |                |                 |                 |                 |                                                                                     |                            |
| 80              | M12            | 60             | 3,0            | –              | 12             | 17              | –               | 18              | 186                                                                                 | <a href="#">22593.1705</a> |
| 80              | M12            | 80             | 3,0            | –              | 12             | 17              | –               | 18              | 199                                                                                 | <a href="#">22593.1710</a> |
| 80              | M12            | 100            | 3,0            | –              | 12             | 17              | –               | 18              | 218                                                                                 | <a href="#">22593.1715</a> |
| 80              | M12            | 125            | 3,0            | –              | 12             | 17              | –               | 18              | 231                                                                                 | <a href="#">22593.1720</a> |
| 有螺丝 – 相片 2, 不锈钢 |                |                |                |                |                |                 |                 |                 |                                                                                     |                            |
| 40              | M16            | 75             | 2,0            | –              | 17             | 12              | 8               | 24              | 154                                                                                 | <a href="#">22593.2105</a> |
| 40              | M16            | 100            | 2,0            | –              | 17             | 12              | 8               | 24              | 183                                                                                 | <a href="#">22593.2110</a> |
| 40              | M16            | 125            | 2,0            | –              | 17             | 12              | 8               | 24              | 217                                                                                 | <a href="#">22593.2115</a> |
| 40              | M16            | 150            | 2,0            | –              | 17             | 12              | 8               | 24              | 252                                                                                 | <a href="#">22593.2120</a> |
| 40              | M16            | 200            | 2,0            | –              | 17             | 12              | 8               | 24              | 315                                                                                 | <a href="#">22593.2125</a> |
| 50              | M16            | 75             | 2,5            | –              | 17             | 12              | 8               | 24              | 172                                                                                 | <a href="#">22593.2130</a> |
| 50              | M16            | 100            | 2,5            | –              | 17             | 12              | 8               | 24              | 205                                                                                 | <a href="#">22593.2135</a> |
| 50              | M16            | 125            | 2,5            | –              | 17             | 12              | 8               | 24              | 236                                                                                 | <a href="#">22593.2140</a> |
| 50              | M16            | 150            | 2,5            | –              | 17             | 12              | 8               | 24              | 270                                                                                 | <a href="#">22593.2145</a> |
| 50              | M16            | 200            | 2,5            | –              | 17             | 12              | 8               | 24              | 335                                                                                 | <a href="#">22593.2150</a> |
| 60              | M16            | 75             | 2,5            | –              | 17             | 12              | 8               | 24              | 187                                                                                 | <a href="#">22593.2155</a> |
| 60              | M16            | 100            | 2,5            | –              | 17             | 12              | 8               | 24              | 221                                                                                 | <a href="#">22593.2160</a> |
| 60              | M16            | 125            | 2,5            | –              | 17             | 12              | 8               | 24              | 252                                                                                 | <a href="#">22593.2165</a> |
| 60              | M16            | 150            | 2,5            | –              | 17             | 12              | 8               | 24              | 288                                                                                 | <a href="#">22593.2170</a> |
| 60              | M16            | 200            | 2,5            | –              | 17             | 12              | 8               | 24              | 352                                                                                 | <a href="#">22593.2175</a> |
| 80              | M16            | 75             | 3,0            | –              | 18             | 12              | 8               | 24              | 251                                                                                 | <a href="#">22593.2180</a> |
| 80              | M16            | 100            | 3,0            | –              | 18             | 12              | 8               | 24              | 285                                                                                 | <a href="#">22593.2185</a> |
| 80              | M16            | 125            | 3,0            | –              | 18             | 12              | 8               | 24              | 317                                                                                 | <a href="#">22593.2190</a> |
| 80              | M16            | 150            | 3,0            | –              | 18             | 12              | 8               | 24              | 349                                                                                 | <a href="#">22593.2195</a> |
| 80              | M16            | 200            | 3,0            | –              | 18             | 12              | 8               | 24              | 414                                                                                 | <a href="#">22593.2200</a> |
| 80              | M20            | 75             | 3,0            | –              | 19             | 15              | 10              | 30              | 340                                                                                 | <a href="#">22593.2205</a> |
| 80              | M20            | 100            | 3,0            | –              | 19             | 15              | 10              | 30              | 393                                                                                 | <a href="#">22593.2210</a> |
| 80              | M20            | 125            | 3,0            | –              | 19             | 15              | 10              | 30              | 441                                                                                 | <a href="#">22593.2215</a> |
| 80              | M20            | 150            | 3,0            | –              | 19             | 15              | 10              | 30              | 494                                                                                 | <a href="#">22593.2220</a> |
| 80              | M20            | 200            | 3,0            | –              | 19             | 15              | 10              | 30              | 600                                                                                 | <a href="#">22593.2225</a> |
| 80              | M24            | 100            | 3,0            | –              | 22             | 19              | 12              | 36              | 537                                                                                 | <a href="#">22593.2230</a> |
| 80              | M24            | 125            | 3,0            | –              | 22             | 19              | 12              | 36              | 610                                                                                 | <a href="#">22593.2235</a> |
| 80              | M24            | 150            | 3,0            | –              | 22             | 19              | 12              | 36              | 681                                                                                 | <a href="#">22593.2240</a> |
| 80              | M24            | 200            | 3,0            | –              | 22             | 19              | 12              | 36              | 829                                                                                 | <a href="#">22593.2245</a> |
| 有母牙 – 相片 3, 不锈钢 |                |                |                |                |                |                 |                 |                 |                                                                                     |                            |
| 40              | M 8            | 25             | 2,0            | 8              | –              | 14              | –               | –               | 41                                                                                  | <a href="#">22593.2505</a> |
| 40              | M10            | 28             | 2,0            | 10             | –              | 14              | –               | –               | 40                                                                                  | <a href="#">22593.2510</a> |
| 40              | M12            | 31             | 2,0            | 12             | –              | 17              | –               | –               | 57                                                                                  | <a href="#">22593.2515</a> |
| 40              | M16            | 37             | 2,0            | 16             | –              | 22              | –               | –               | 93                                                                                  | <a href="#">22593.2520</a> |
| 50              | M 8            | 25             | 2,5            | 8              | –              | 14              | –               | –               | 59                                                                                  | <a href="#">22593.2525</a> |
| 50              | M10            | 28             | 2,5            | 10             | –              | 14              | –               | –               | 58                                                                                  | <a href="#">22593.2530</a> |
| 50              | M12            | 32             | 2,5            | 12             | –              | 17              | –               | –               | 76                                                                                  | <a href="#">22593.2535</a> |
| 50              | M16            | 37             | 2,5            | 16             | –              | 22              | –               | –               | 112                                                                                 | <a href="#">22593.2540</a> |
| 60              | M 8            | 25             | 2,5            | 8              | –              | 14              | –               | –               | 76                                                                                  | <a href="#">22593.2545</a> |
| 60              | M10            | 28             | 2,5            | 10             | –              | 14              | –               | –               | 77                                                                                  | <a href="#">22593.2550</a> |
| 60              | M12            | 32             | 2,5            | 12             | –              | 17              | –               | –               | 92                                                                                  | <a href="#">22593.2555</a> |
| 60              | M16            | 37             | 2,5            | 16             | –              | 22              | –               | –               | 127                                                                                 | <a href="#">22593.2560</a> |
| 80              | M 8            | 26             | 3,0            | 8              | –              | 14              | –               | –               | 140                                                                                 | <a href="#">22593.2565</a> |
| 80              | M10            | 29             | 3,0            | 10             | –              | 14              | –               | –               | 144                                                                                 | <a href="#">22593.2570</a> |
| 80              | M12            | 32             | 3,0            | 12             | –              | 17              | –               | –               | 160                                                                                 | <a href="#">22593.2575</a> |
| 80              | M16            | 38             | 3,0            | 16             | –              | 22              | –               | –               | 195                                                                                 | <a href="#">22593.2580</a> |
| 80              | M20            | 45             | 3,0            | 20             | –              | 27              | –               | –               | 256                                                                                 | <a href="#">22593.2585</a> |

遵守

For detailed compliance information please select the desired article number.