

油面镜
EH 22860.



产品描述

适合没有过压的油箱.


材质

- 密封环
 - 抗油品
- 反射器
 - 塑胶，白色
- 环型螺帽
 - 铝
- 油面镜
 - 塑料玻璃 (PMMA) - 透明的

组装

在钻孔中可不用装置线 Ø H11. 透过简单拧紧环形螺母来密封。

图面

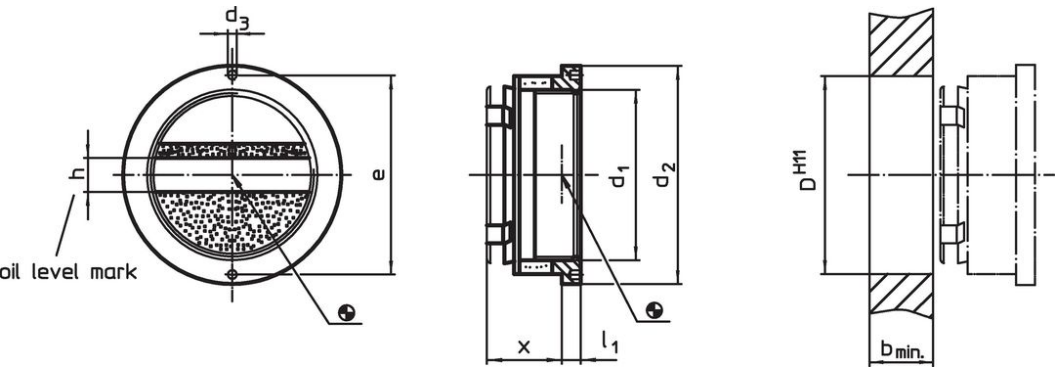


订单信息

尺寸								定位孔				品号
尺寸(视界开口) d ₁	d ₂	d ₃	x ~	l ₁	b min	h	e	D H11	min	max.		
[mm]								[mm]	[°C]		[g]	
无 油高标示												
16	25	2,2	15	3,5	9	–	21,0	20	-20	70	9,1	22860.0016
22	35	3,0	15	4,5	10	–	30,0	28	-20	70	18,0	22860.0022
32	45	3,0	18	5,5	12	–	40,0	38	-20	70	34,0	22860.0032
50	64	3,0	22	5,5	14	–	58,5	58	-20	70	87,0	22860.0050
有 油高标示												
16	25	2,2	15	3,5	9	5	21,0	20	-20	70	9,2	22860.0116
22	35	3,0	15	4,5	10	6	30,0	28	-20	70	18,0	22860.0122
32	45	3,0	18	5,5	12	8	40,0	38	-20	70	33,0	22860.0132
50	64	3,0	22	5,5	14	10	58,5	58	-20	70	85,0	22860.0150

配件

	尺寸(视界开口)	尺寸			品号
	d ₁	d h9	e		
	[mm]			[g]	
组立工具					
	16	2,0	21,0	16	22860.0816
	22	2,8	30,0	30	22860.0822
	32	2,8	40,0	36	22860.0832
	50	2,8	58,5	49	22860.0850

应用范例

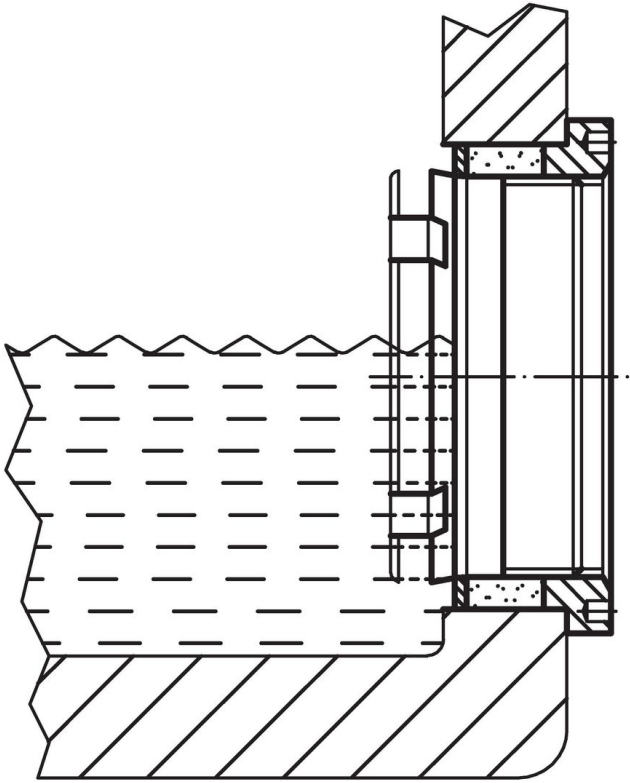

遵守

For detailed compliance information please select the desired article number.