

夹持把手
EH 24430.




产品描述

材质

- 把手
- 钢，染黑
 - 不锈钢 1.4305，钝化喷砂
- 球形把手
- PF 31 塑胶，黑色, DIN 319


图面

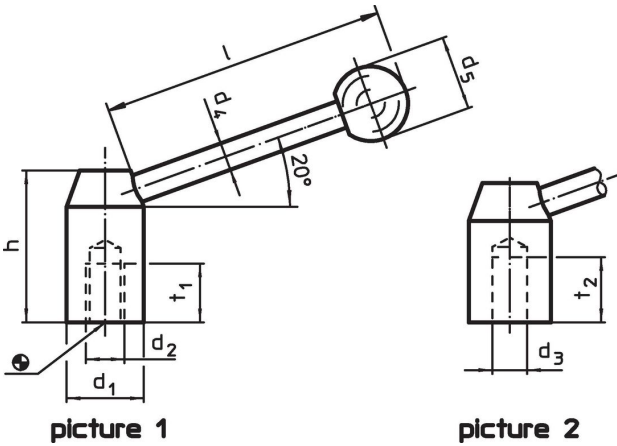

订单信息

尺寸 d₁ d₂ d₃ H7 d₄ d₅ h l t₁ t₂ [mm]										 [g]	品号
有母牙 – 相片 1, 钢											
20	M 8	–	8	20	33	67	15	–	97		24430.0022
22	M10	–	8	20	37	85	15	–	115		24430.0032
25	M12	–	10	25	42	95	18	–	165		24430.0038
28	M12	–	12	30	47	108	18	–	262		24430.0042
32	M16	–	12	32	52	126	23	–	354		24430.0048
36	M16	–	14	35	58	138	24	–	519		24430.0052
40	M20	–	16	40	64	154	27	–	708		24430.0058
有平滑孔 – 相片 2, 钢											
20	–	10	8	20	33	67	–	16	85		24430.0020
22	–	10	8	20	37	85	–	19	113		24430.0030
25	–	12	10	25	42	95	–	21	170		24430.0035
28	–	12	12	30	47	108	–	23	268		24430.0040
32	–	16	12	32	52	126	–	28	351		24430.0045
36	–	16	14	35	58	138	–	28	524		24430.0050
40	–	20	16	40	64	154	–	30	706		24430.0055
有母牙 – 相片 1, 不锈钢											
22	M 8	–	8	20	37	85	15	–	121		24430.0230
25	M10	–	10	25	42	95	18	–	186		24430.0236
28	M12	–	12	30	47	108	18	–	262		24430.0242
32	M16	–	12	32	52	126	23	–	354		24430.0248

应用范例

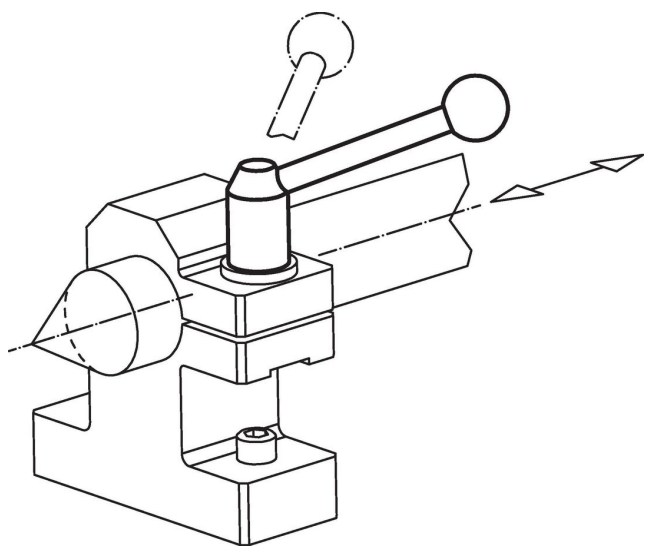

遵守

For detailed compliance information please select the desired article number.