

旋钮把手
EH 24520.




产品描述

材质

- 钢，染黑
- 不锈钢 1.4305，钝化喷砂

图面

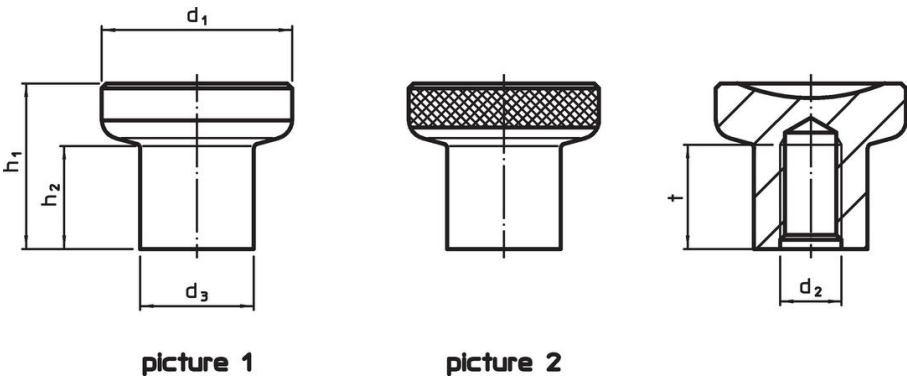


订单信息

尺寸				品号				
d ₁	d ₂	d ₃			h ₁	h ₂	t min	
[mm]						[g]		
无压花 – 相片 1, 钢								
21	M 4	12,5	18,0	10,5	10	26	24520.0002	
21	M 5	12,5	18,0	10,5	10	25	24520.0003	
25	M 6	14,5	22,5	14,0	12	42	24520.0005	
25	M 8	14,5	22,5	14,0	12	38	24520.0006	
31	M 8	18,5	27,0	17,0	15	75	24520.0008	
31	M10	18,5	27,0	17,0	17	70	24520.0009	
有压花 – 相片 2, 钢								
21	M 4	12,5	18,0	10,5	10	26	24520.0022	
21	M 5	12,5	18,0	10,5	10	25	24520.0023	
25	M 6	14,5	22,5	14,0	12	42	24520.0025	
25	M 8	14,5	22,5	14,0	12	39	24520.0026	
31	M 8	18,5	27,0	17,0	15	75	24520.0028	
31	M10	18,5	27,0	17,0	17	70	24520.0029	
无压花 – 相片 1, 不锈钢								
21	M 4	12,5	18,0	10,5	10	26	24520.0102	
21	M 5	12,5	18,0	10,5	10	25	24520.0103	
25	M 6	14,5	22,5	14,0	12	42	24520.0105	
25	M 8	14,5	22,5	14,0	12	38	24520.0106	
31	M 8	18,5	27,0	17,0	15	75	24520.0108	
31	M10	18,5	27,0	17,0	17	70	24520.0109	

d ₁	d ₂	d ₃	尺寸				品号
			h ₁	h ₂	t min		
			[mm]				
有压花 – 相片 2, 不锈钢							
21	M 4	12,5	18,0	10,5	10	26	24520.0122
21	M 5	12,5	18,0	10,5	10	25	24520.0123
25	M 6	14,5	22,5	14,0	12	42	24520.0125
25	M 8	14,5	22,5	14,0	12	39	24520.0126
31	M 8	18,5	27,0	17,0	15	75	24520.0128
31	M10	18,5	27,0	17,0	17	70	24520.0129

应用范例

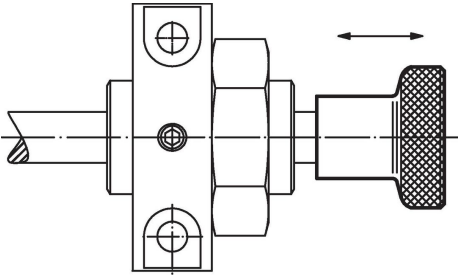

遵守

For detailed compliance information please select the desired article number.