


Tvarované rukojeti
EH 24520.

Popis produktu


Materiál

- Ocel, bryněrovaná
- Nerez 1.4305, matná


Výkres s rozměry

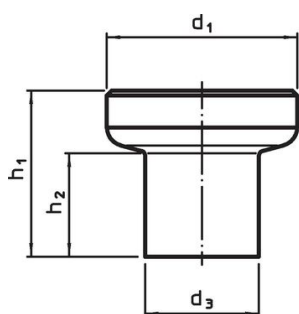

Obr. 1

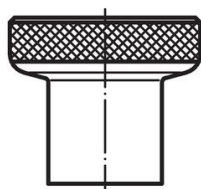

Obr. 2

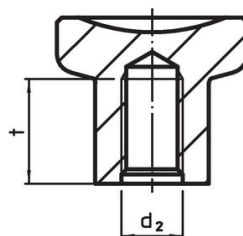


Informace pro objednání

d ₁	d ₂	d ₃	Rozměry			t min.		Obj. č.
			[mm]					
bez rýhování – obrázek 1, Ocel								
21	M 4	12,5	18,0	10,5	10	26	24520.0002	
21	M 5	12,5	18,0	10,5	10	25	24520.0003	
25	M 6	14,5	22,5	14,0	12	42	24520.0005	
25	M 8	14,5	22,5	14,0	12	38	24520.0006	
31	M 8	18,5	27,0	17,0	15	75	24520.0008	
31	M10	18,5	27,0	17,0	17	70	24520.0009	
s rýhováním – obrázek 2, Ocel								
21	M 4	12,5	18,0	10,5	10	26	24520.0022	
21	M 5	12,5	18,0	10,5	10	25	24520.0023	
25	M 6	14,5	22,5	14,0	12	42	24520.0025	
25	M 8	14,5	22,5	14,0	12	39	24520.0026	
31	M 8	18,5	27,0	17,0	15	75	24520.0028	
31	M10	18,5	27,0	17,0	17	70	24520.0029	
bez rýhování – obrázek 1, Nerez								
21	M 4	12,5	18,0	10,5	10	26	24520.0102	
21	M 5	12,5	18,0	10,5	10	25	24520.0103	
25	M 6	14,5	22,5	14,0	12	42	24520.0105	
25	M 8	14,5	22,5	14,0	12	38	24520.0106	
31	M 8	18,5	27,0	17,0	15	75	24520.0108	
31	M10	18,5	27,0	17,0	17	70	24520.0109	

Rozměry							Obj. č.
d ₁	d ₂	d ₃	h ₁	h ₂	t min.		
[mm]						[g]	
s rýhováním – obrázek 2, Nerez							
21	M 4	12,5	18,0	10,5	10	26	24520.0122
21	M 5	12,5	18,0	10,5	10	25	24520.0123
25	M 6	14,5	22,5	14,0	12	42	24520.0125
25	M 8	14,5	22,5	14,0	12	39	24520.0126
31	M 8	18,5	27,0	17,0	15	75	24520.0128
31	M10	18,5	27,0	17,0	17	70	24520.0129

Příklad použití

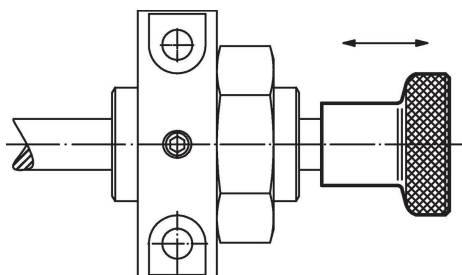

Shoda

Pro podrobné informace o shodě vyberte, prosím, požadované číslo výrobku.