

Feste Ballengriffe • DIN 39  
EH 24450.



Produktbeschreibung

Werkstoff

- Stahl, gedreht, galvanisch verzinkt, passiviert
- Rostfreier Stahl 1.4404

Maßzeichnung

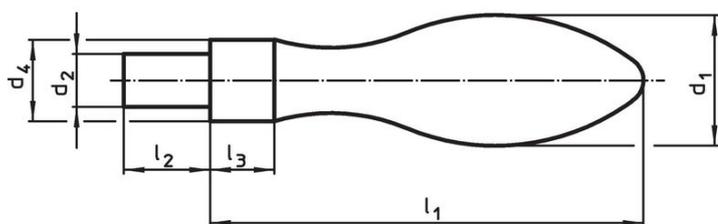


Bild 1

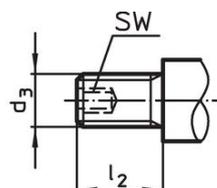


Bild 2


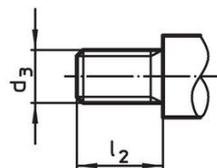


Bild 3

Bestellinformationen

d <sub>1</sub>	d <sub>2</sub> h8	d <sub>3</sub>	Abmessungen				SW	[g]	Art.-Nr.
			d <sub>4</sub> h13 [mm]	l <sub>1</sub> ~	l <sub>2</sub>	l <sub>3</sub>			
<b>mit glattem Zapfen, Form D – Bild 1, Stahl</b>									
16	7	–	10	50	11	7	–	45	<a href="#">24450.0016</a>
20	8	–	13	64	13	8	–	92	<a href="#">24450.0020</a>
25	10	–	16	80	14	10	–	179	<a href="#">24450.0025</a>
32	13	–	20	100	21	13	–	356	<a href="#">24450.0032</a>
36	16	–	22	112	26	14	–	519	<a href="#">24450.0036</a>
<b>mit Gewindezapfen, Form E – Bild 2, Stahl</b>									
16	–	M 6	10	50	11	7	3	43	<a href="#">24450.0116</a>
20	–	M 8	13	64	13	8	4	88	<a href="#">24450.0120</a>
25	–	M10	16	80	14	10	5	175	<a href="#">24450.0125</a>
32	–	M12	20	100	21	13	6	340	<a href="#">24450.0132</a>
36	–	M16	22	112	26	14	8	509	<a href="#">24450.0136</a>
<b>mit Gewindezapfen, Form E – Bild 3, Rostfreier Stahl</b>									
16	–	M 6	10	50	11	7	–	45	<a href="#">24450.0316</a>
20	–	M 8	13	64	13	8	–	92	<a href="#">24450.0320</a>
25	–	M10	16	80	14	10	–	186	<a href="#">24450.0325</a>

Anwendungsbeispiel

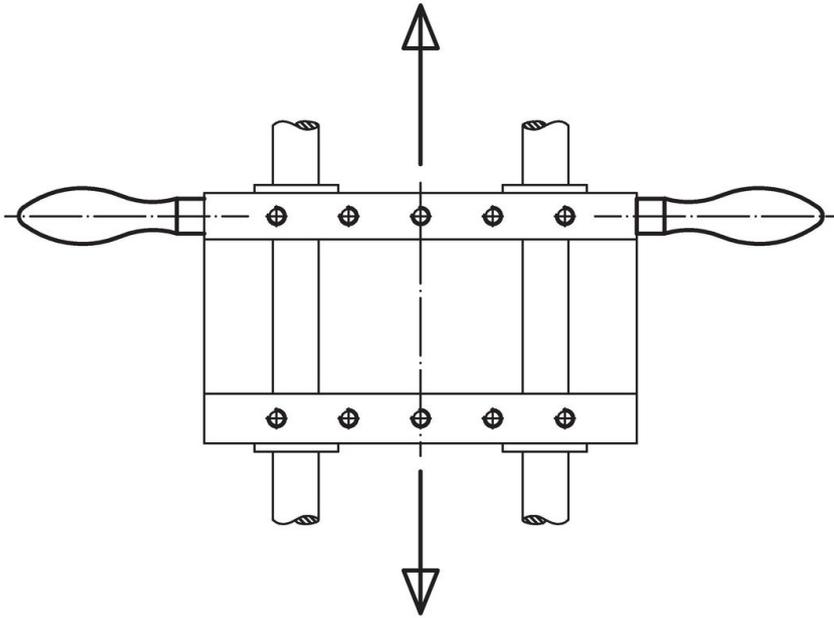

Compliance

Für detaillierte Compliance Informationen wählen Sie bitte die gewünschte Artikelnummer.