


## PACKED FULL OF POWER: THE SUPERCRAFT PRINCIPLE

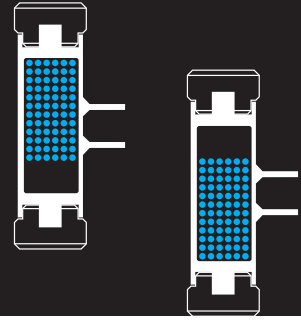

### Non-rebound work

- 1** Joint-friendly
- 2** Reduced noise
- 3** Very high impact strength
- 4** Wear resistant inserts

**HALDER**

## SLAMMING WITH MANUFACTURING QUALITY

**THE  
ORIGINAL  
MADE IN  
GERMANY.**



### ERWIN HALDER KG

Erwin-Halder-Straße 5-9  
88480 Achstetten-Bronnen  
Germany

 
Phone +49 7392 7009-0  
FAX +49 7392 7009-160  
info@halder.com  
www.halder.com




**HALDER**

## THE ORIGINAL FOR PROFESSIONALS

Soft-face mallets and forestry tools



## SIMPLY SMART: THE SIMPLEX PRINCIPLE

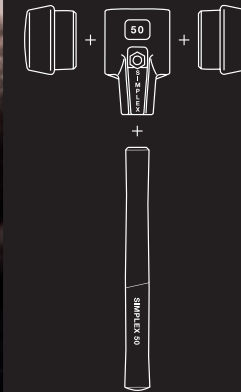

- 1** All wear parts can be easily replaced at any time
- 2** Interchangeable insert faces with different degrees of hardness
- 3** Housings of cast steel, aluminum or reinforced cast steel
- 4** High-quality wood or fibreglass handles



→ **TPE-SOFT**  
soft / non-marring  
hardness ●○○○○



→ **RUBBER COMPOSITION**  
medium hard / impact cushioning  
odorless / low-wear  
hardness ●●○○○



→ **TPE-MID**  
medium hard / non-marring  
hardness ●●○○○



→ **SUPERPLASTIC**  
medium-hard / very durable  
wear-resistant  
hardness ●●●○○



→ **PLASTIC**  
hard / oil and grease resistant  
hardness ●●●●○



→ **NYLON**  
hard / very wear-resistant  
no chipping / oil and grease resistant  
hardness ●●●●○



→ **SOFT METAL**  
hard / heat-proof  
hardness ●●●●●



→ **COPPER**  
with plastic socket / hard  
hardness ●●●●●

# THE PERFECT HAMMER FOR EACH JOB



Both as a pro and as a handyman, you need two things to get excellent work results: the ambition to always do a top job, and the tools to support you in this.

For nearly 80 years, Halder soft-face mallets and forestry tools have stood for smart solutions and materials of the highest quality, made in Germany.



## CONSTRUCTION / GARDENING / LANDSCAPING

### → Curbstone setting, paving

3027 SIMPLEX-soft-face mallet · Rubber comp./Superplastic · Ø 30-80 mm

### → Curbstone setting

3027 SIMPLEX-sledge hammer · Rubber comp./Superplastic · Ø 80 mm

### → Natural stone setting, masonry-/stairs setting

3013 SIMPLEX-soft-face mallet · TPE-soft/TPE-mid · Ø 30-60 mm

### → Concrete formwork

3366 SUPERCRAFT-sledge hammer, non-rebound · Ø 80-100 mm

## MAINTENANCE / REPAIR

### → Mild to moderate work

3968 BASEPLEX-hammer · Cellulose acetate/Nylon · Ø 25-50 mm

3026 SIMPLEX-soft-face mallet · Rubber comp./Plastic · Ø 30-60 mm

### → Powerful work

3366 SUPERCRAFT-soft-face mallet, non-rebound · Hickory handle · Ø 20-80 mm

3666 MAXXCRAFT-Locksmith's hammer · 300-1000 g

### → Automotive and truck sector

3029 SIMPLEX-soft-face mallet · Rubber comp./Soft metal · Ø 30-80 mm

3749 SIMPLEX-soft-face mallet · Copper/Soft metal · Ø 30-40 mm

3677 FERROPLEX-Combi hammer · Ø 30-35 mm

3379 BLACKCRAFT-soft-face mallet, non-rebound · Ø 40-60

3408 Punch · Ø 10-15 mm

### → Tire

3377 SUPERCRAFT-soft-face mallet, non-rebound · Steel tube handle · Ø 25-70 mm

3379 BLACKCRAFT-soft-face mallet, non-rebound · Ø 40-60

## JOINERY / CARPENTRY

### → Setting light/sensitive workpieces, veneering

3117 SIMPLEX-soft-face mallet · TPE-soft/Superplastic · 50:40 · Ø 50 mm

### → Furniture assembly

3013 SIMPLEX-soft-face mallet · TPE-soft/TPE-mid · Ø 30-60 mm

### → Pin driving

3666 MAXXCRAFT-Locksmith's hammer · 300-1000 g

### → Roof setting

3366 SUPERCRAFT-sledge hammer, non-rebound · Ø 80-100 mm

## INTERIOR WORK

### → Parquet and laminte flooring

3380 SECURAL-soft-face mallet, non-rebound · 30x40 mm

3666 MAXXCRAFT-Locksmith's hammer · 300-1000 g

### → Floor tiling, drywall construction

3013 SIMPLEX-soft-face mallet · TPE-soft/TPE-mid · Ø 30-60 mm

3380 SECURAL-soft-face mallet, non rebound · 30x40 mm

### → Install ceiling moldings

3408 Drop-mallet, non-rebound · Ø 20-50 mm

## SHEET METAL FORMING

### → Folding and bending work

3366 SUPERCRAFT-soft-face mallet, non-rebound · Hickory handle · Ø 20-80 mm

3380 SECURAL-soft-face mallet, non rebound · 30x40 mm

3748 SIMPLEX-soft-face mallet · Copper/Soft metal · Ø 30-40 mm

### → Installation work

3380 SECURAL-soft-face mallet, non rebound · 30x40 mm

3906 BASEPLEX-hammer · Cellulose acetate · Ø 25-50 mm

3677 FERROPLEX-Combi hammer · Ø 30-35 mm

## METALWORKING INDUSTRY

### → Positioning and adjusting of workpieces

3366 SUPERCRAFT-soft-face mallet, non-rebound · Hickory handle · Ø 20-80 mm

3389 SUPERCRAFT-soft-face mallet, non-rebound · 3-comp.-handle · Ø 40-60 mm

3377 SUPERCRAFT-soft-face mallet, non-rebound · Steel tube handle · Ø 25-70 mm

3388 SECURAL-soft-face mallet, non rebound · 30x40 mm

3408 Drop-mallet, non-rebound · Ø 20-50 mm

### → Straightening work, plant construction

3749 SIMPLEX-soft-face mallet · Copper/Soft metal · Ø 30-40 mm

3666 MAXXCRAFT-Locksmith's hammer · 300-1000 g

### → Housing assembly, mould construction

3089 SIMPLEX-soft-face mallet · Nylon/Soft metal · Ø 30-80 mm

## AGRICULTURE / FORESTRY

### → Fence construction

3007 SIMPLEX-sledge hammer · Superplastic · Ø 80-140 mm

3366 SUPERCRAFT-sledge hammer, non rebound · Ø 80-100 mm

### → Splitting 1-metre logs, wedge work

3007 SIMPLEX-splitting maul

### → Splitting wood, wedge work

3007 SIMPLEX-splitting axe

### → Splitting 1-metre logs

3556 Halder twisted splitting wedge

### → Splitting of smaller logs/kindling

3555 Halder hand axe · forged

Further models and combinations, see [www.halder.com](http://www.halder.com)