

Brazos de Fijación EH 24430.



Descripción del producto

Material


Empuñadura

- Acero, pavonado
- Acero inoxidable 1.4305, mate

Bola

- Baquelita PF 31, negro, DIN 319


Dibujo

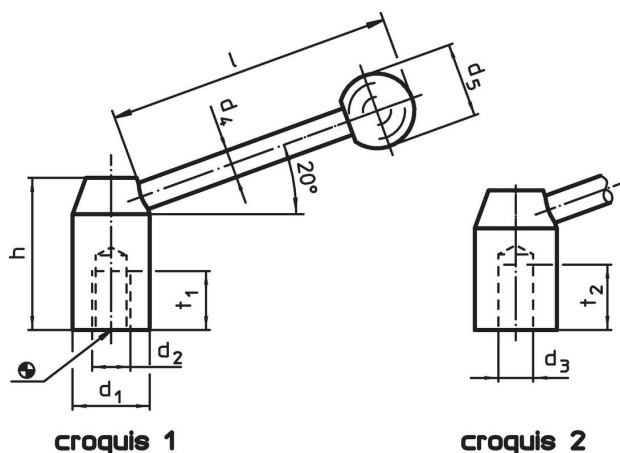

Información para el pedido

d ₁	d ₂	d ₃ H7	d ₄	Dimensiones		h	l ~	t ₁	t ₂	 [g]	Referencia
				d ₅	[mm]						
con rosca hembra – croquis 1, Acero											
20	M 8	–	8	20	33	67	15	–	97		24430.0022
22	M10	–	8	20	37	85	15	–	115		24430.0032
25	M12	–	10	25	42	95	18	–	165		24430.0038
28	M12	–	12	30	47	108	18	–	262		24430.0042
32	M16	–	12	32	52	126	23	–	354		24430.0048
36	M16	–	14	35	58	138	24	–	519		24430.0052
40	M20	–	16	40	64	154	27	–	708		24430.0058
con taladro liso – croquis 2, Acero											
20	–	10	8	20	33	67	–	16	85		24430.0020
22	–	10	8	20	37	85	–	19	113		24430.0030
25	–	12	10	25	42	95	–	21	170		24430.0035
28	–	12	12	30	47	108	–	23	268		24430.0040
32	–	16	12	32	52	126	–	28	351		24430.0045
36	–	16	14	35	58	138	–	28	524		24430.0050
40	–	20	16	40	64	154	–	30	706		24430.0055
con rosca hembra – croquis 1, Acero inoxidable											
22	M 8	–	8	20	37	85	15	–	121		24430.0230
25	M10	–	10	25	42	95	18	–	186		24430.0236
28	M12	–	12	30	47	108	18	–	262		24430.0242
32	M16	–	12	32	52	126	23	–	354		24430.0248

Ejemplo de aplicación

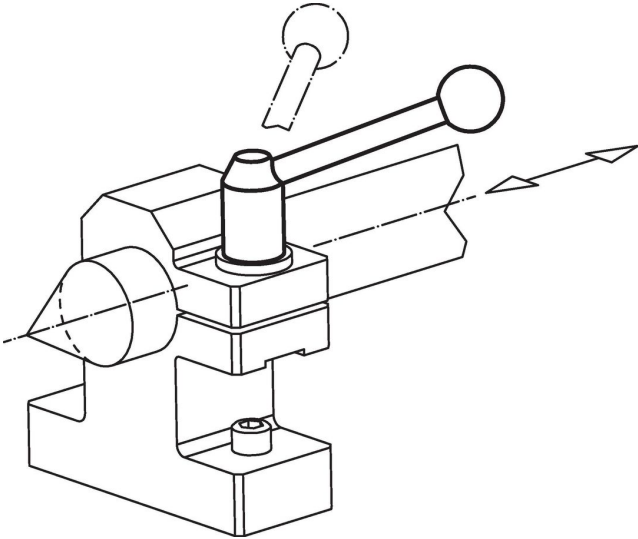

Cumplimiento

Para obtener información detallada sobre el cumplimiento, seleccione el número de artículo deseado.