

Thumb Knobs

EH 24520.




Product Description


Material

- Steel, blackened
- Stainless steel 1.4305, dull blasted


Drawing

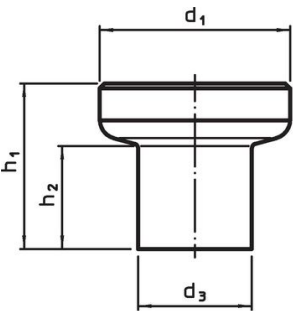

picture 1

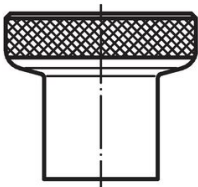

picture 2

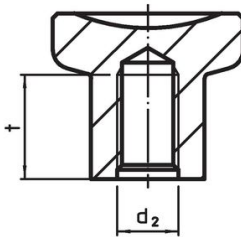


Order information

Dimensions							Art. No.
d ₁	d ₂	d ₃	h ₁	h ₂	t min.	[g]	
[mm]							
without knurling – picture 1, Steel							
21	M 4	12.5	18.0	10.5	10	26	24520.0002
21	M 5	12.5	18.0	10.5	10	25	24520.0003
25	M 6	14.5	22.5	14.0	12	42	24520.0005
25	M 8	14.5	22.5	14.0	12	38	24520.0006
31	M 8	18.5	27.0	17.0	15	75	24520.0008
31	M10	18.5	27.0	17.0	17	70	24520.0009
with knurling – picture 2, Steel							
21	M 4	12.5	18.0	10.5	10	26	24520.0022
21	M 5	12.5	18.0	10.5	10	25	24520.0023
25	M 6	14.5	22.5	14.0	12	42	24520.0025
25	M 8	14.5	22.5	14.0	12	39	24520.0026
31	M 8	18.5	27.0	17.0	15	75	24520.0028
31	M10	18.5	27.0	17.0	17	70	24520.0029
without knurling – picture 1, Stainless steel							
21	M 4	12.5	18.0	10.5	10	26	24520.0102
21	M 5	12.5	18.0	10.5	10	25	24520.0103
25	M 6	14.5	22.5	14.0	12	42	24520.0105
25	M 8	14.5	22.5	14.0	12	38	24520.0106
31	M 8	18.5	27.0	17.0	15	75	24520.0108
31	M10	18.5	27.0	17.0	17	70	24520.0109

Dimensions							Art. No.
d ₁	d ₂	d ₃	h ₁	h ₂	t min.	[g]	
[mm]							
with knurling – picture 2, Stainless steel							
21	M 4	12.5	18.0	10.5	10	26	24520.0122
21	M 5	12.5	18.0	10.5	10	25	24520.0123
25	M 6	14.5	22.5	14.0	12	42	24520.0125
25	M 8	14.5	22.5	14.0	12	39	24520.0126
31	M 8	18.5	27.0	17.0	15	75	24520.0128
31	M10	18.5	27.0	17.0	17	70	24520.0129

Application example

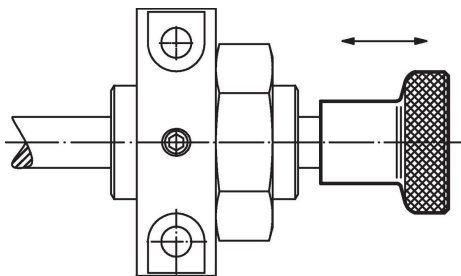

Compliance

For detailed compliance information please select the desired article number.