

Duimknoppen
EH 24520.




Productbeschrijving

Materiaal

- staal, gezwart
- RVS 1.4305, mat gestraald


Tekening

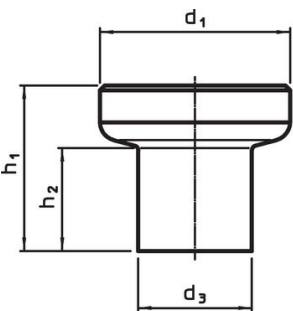

Afbeelding 1



Afbeelding 2

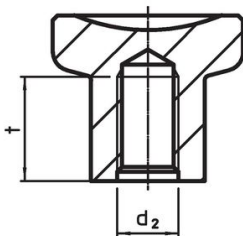


Bestelinformatie

Afmetingen							Artikelnr.
d ₁	d ₂	d ₃	h ₁	h ₂	t min.		
[mm]						[g]	
zonder kartelrand – Afbeelding 1, Staal							
21	M 4	12,5	18,0	10,5	10	26	24520.0002
21	M 5	12,5	18,0	10,5	10	25	24520.0003
25	M 6	14,5	22,5	14,0	12	42	24520.0005
25	M 8	14,5	22,5	14,0	12	38	24520.0006
31	M 8	18,5	27,0	17,0	15	75	24520.0008
31	M10	18,5	27,0	17,0	17	70	24520.0009
met kartelrand – Afbeelding 2, Staal							
21	M 4	12,5	18,0	10,5	10	26	24520.0022
21	M 5	12,5	18,0	10,5	10	25	24520.0023
25	M 6	14,5	22,5	14,0	12	42	24520.0025
25	M 8	14,5	22,5	14,0	12	39	24520.0026
31	M 8	18,5	27,0	17,0	15	75	24520.0028
31	M10	18,5	27,0	17,0	17	70	24520.0029
zonder kartelrand – Afbeelding 1, Roestvast staal							
21	M 4	12,5	18,0	10,5	10	26	24520.0102
21	M 5	12,5	18,0	10,5	10	25	24520.0103
25	M 6	14,5	22,5	14,0	12	42	24520.0105
25	M 8	14,5	22,5	14,0	12	38	24520.0106
31	M 8	18,5	27,0	17,0	15	75	24520.0108
31	M10	18,5	27,0	17,0	17	70	24520.0109

Afmetingen							Artikelnr.
d ₁	d ₂	d ₃	h ₁	h ₂	t min.	[g]	
[mm]							
met kartelrand – Afbeelding 2, Roestvast staal							
21	M 4	12,5	18,0	10,5	10	26	24520.0122
21	M 5	12,5	18,0	10,5	10	25	24520.0123
25	M 6	14,5	22,5	14,0	12	42	24520.0125
25	M 8	14,5	22,5	14,0	12	39	24520.0126
31	M 8	18,5	27,0	17,0	15	75	24520.0128
31	M10	18,5	27,0	17,0	17	70	24520.0129

Toepassingsvoorbeeld

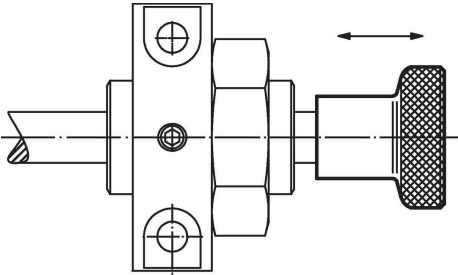

Voldoet

Selecteer voor gedetailleerde informatie over de naleving het gewenste artikelnummer.