

Dźwignie mocujące
EH 24430.

Opis produktu

Materiał


Dźwignia

- Stal oksydowana
- Stal nierdzewna 1.4305, piaskowana

Gałka kulista

- Tworzywo termoutwardzalne PF 31, czarne, DIN 319

Rysunek

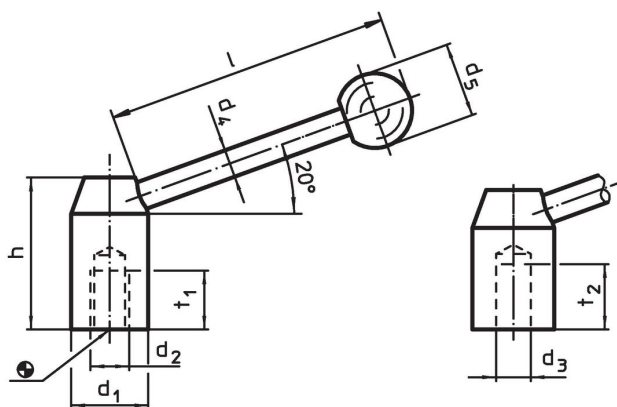


Rysunek 1

Rysunek 2

Informacje do zamówienia

d ₁	d ₂	d ₃ H7	d ₄	Wymiary d ₅		h	l ~	t ₁	t ₂		Nr art.
[mm]										[g]	
z gwintem wewnętrznym – rysunek 1, Stal											
20	M 8	–	8	20	33	67	15	–	97	24430.0022	
22	M10	–	8	20	37	85	15	–	115	24430.0032	
25	M12	–	10	25	42	95	18	–	165	24430.0038	
28	M12	–	12	30	47	108	18	–	262	24430.0042	
32	M16	–	12	32	52	126	23	–	354	24430.0048	
36	M16	–	14	35	58	138	24	–	519	24430.0052	
40	M20	–	16	40	64	154	27	–	708	24430.0058	
z gładkim otworem – rysunek 2, Stal											
20	–	10	8	20	33	67	–	16	85	24430.0020	
22	–	10	8	20	37	85	–	19	113	24430.0030	
25	–	12	10	25	42	95	–	21	170	24430.0035	
28	–	12	12	30	47	108	–	23	268	24430.0040	
32	–	16	12	32	52	126	–	28	351	24430.0045	
36	–	16	14	35	58	138	–	28	524	24430.0050	
40	–	20	16	40	64	154	–	30	706	24430.0055	
z gwintem wewnętrznym – rysunek 1, Stal nierdzewna											
22	M 8	–	8	20	37	85	15	–	121	24430.0230	
25	M10	–	10	25	42	95	18	–	186	24430.0236	
28	M12	–	12	30	47	108	18	–	262	24430.0242	
32	M16	–	12	32	52	126	23	–	354	24430.0248	

Przykład aplikacji

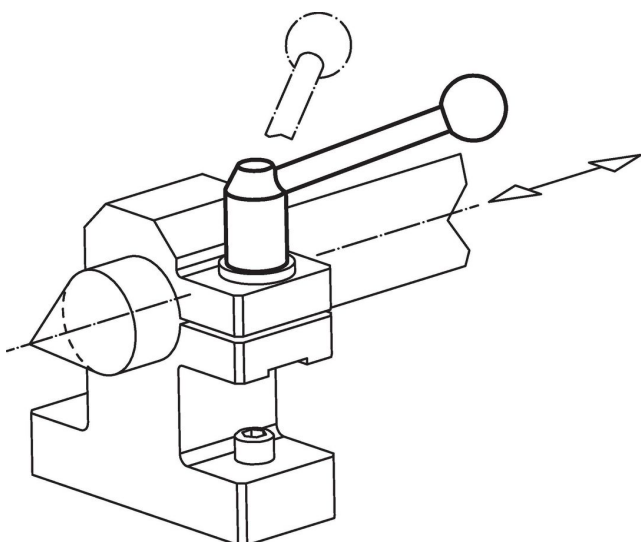

Zgodność

Dla szczegółowych informacji dot. zgodności należy wybrać pożądany numer towaru.