

Maskinhandtag EH 24430.



Produktbeskrivning

Material


Manöverspak

- Stål, svartoxiderat
- Rostfritt stål 1.4305, mattpolerat

Kulknopp

- Hårdplast PF 31, svart, DIN 319


Ritning

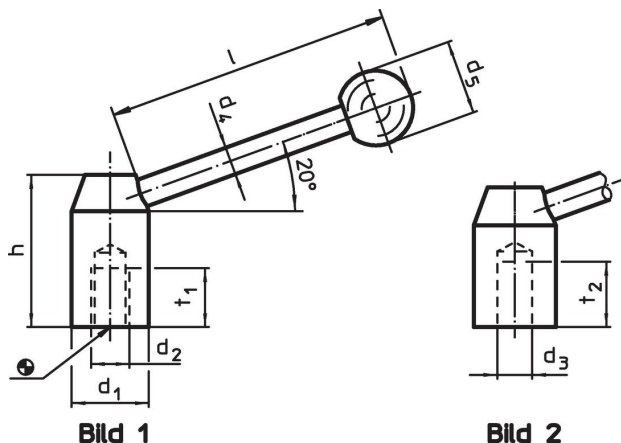

Orderinformation

d ₁	d ₂	d ₃ H7	d ₄	Dimension d ₅ [mm]	h	l ~	t ₁	t ₂	 [g]	Art.nr.
med invändig gänga – Bild 1, stål										
20	M 8	–	8	20	33	67	15	–	97	24430.0022
22	M10	–	8	20	37	85	15	–	115	24430.0032
25	M12	–	10	25	42	95	18	–	165	24430.0038
28	M12	–	12	30	47	108	18	–	262	24430.0042
32	M16	–	12	32	52	126	23	–	354	24430.0048
36	M16	–	14	35	58	138	24	–	519	24430.0052
40	M20	–	16	40	64	154	27	–	708	24430.0058
Med enbart hål – Bild 2, stål										
20	–	10	8	20	33	67	–	16	85	24430.0020
22	–	10	8	20	37	85	–	19	113	24430.0030
25	–	12	10	25	42	95	–	21	170	24430.0035
28	–	12	12	30	47	108	–	23	268	24430.0040
32	–	16	12	32	52	126	–	28	351	24430.0045
36	–	16	14	35	58	138	–	28	524	24430.0050
40	–	20	16	40	64	154	–	30	706	24430.0055
med invändig gänga – Bild 1, rostfritt stål										
22	M 8	–	8	20	37	85	15	–	121	24430.0230
25	M10	–	10	25	42	95	18	–	186	24430.0236
28	M12	–	12	30	47	108	18	–	262	24430.0242
32	M16	–	12	32	52	126	23	–	354	24430.0248

Användningsexempel

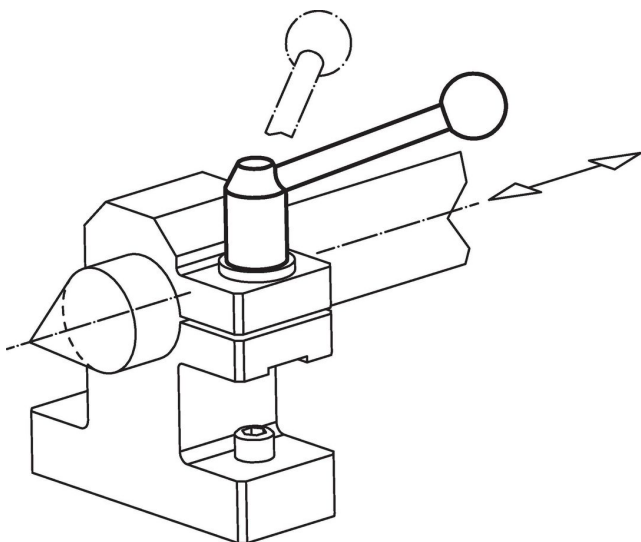

Överensstämmelse

For detailed compliance information please select the desired article number.