

Knopp EH 24520.



Produktbeskrivning

Material

- Stål, svartoxiderat
- Rostfritt stål 1.4305, mattpolerat

Ritning

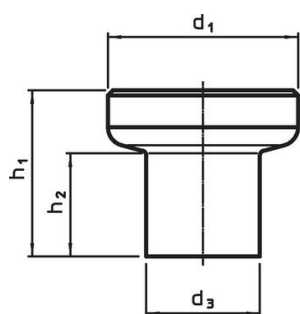


Bild 1


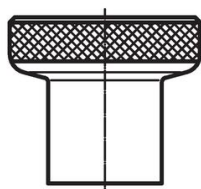


Bild 2

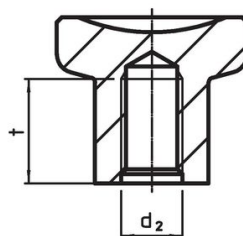


Orderinformation

Dimension								Art.nr.
d ₁	d ₂	d ₃	h ₁	h ₂	t min.			
[mm]						[g]		
Utan räfflor – Bild 1, stål								
21	M 4	12,5	18,0	10,5	10	26	24520.0002	
21	M 5	12,5	18,0	10,5	10	25	24520.0003	
25	M 6	14,5	22,5	14,0	12	42	24520.0005	
25	M 8	14,5	22,5	14,0	12	38	24520.0006	
31	M 8	18,5	27,0	17,0	15	75	24520.0008	
31	M10	18,5	27,0	17,0	17	70	24520.0009	
Med räfflor – Bild 2, stål								
21	M 4	12,5	18,0	10,5	10	26	24520.0022	
21	M 5	12,5	18,0	10,5	10	25	24520.0023	
25	M 6	14,5	22,5	14,0	12	42	24520.0025	
25	M 8	14,5	22,5	14,0	12	39	24520.0026	
31	M 8	18,5	27,0	17,0	15	75	24520.0028	
31	M10	18,5	27,0	17,0	17	70	24520.0029	
Utan räfflor – Bild 1, rostfritt stål								
21	M 4	12,5	18,0	10,5	10	26	24520.0102	
21	M 5	12,5	18,0	10,5	10	25	24520.0103	
25	M 6	14,5	22,5	14,0	12	42	24520.0105	
25	M 8	14,5	22,5	14,0	12	38	24520.0106	
31	M 8	18,5	27,0	17,0	15	75	24520.0108	
31	M10	18,5	27,0	17,0	17	70	24520.0109	

Dimension							Art.nr.
d ₁	d ₂	d ₃	h ₁	h ₂	t min.		
[mm]						[g]	
Med räfflor – Bild 2, rostfritt stål							
21	M 4	12,5	18,0	10,5	10	26	24520.0122
21	M 5	12,5	18,0	10,5	10	25	24520.0123
25	M 6	14,5	22,5	14,0	12	42	24520.0125
25	M 8	14,5	22,5	14,0	12	39	24520.0126
31	M 8	18,5	27,0	17,0	15	75	24520.0128
31	M10	18,5	27,0	17,0	17	70	24520.0129

Användningsexempel

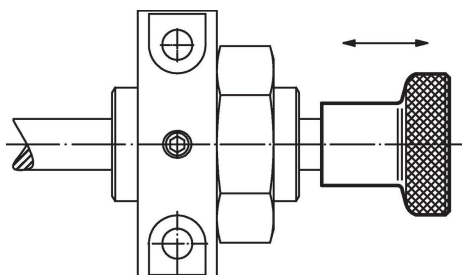

Överensstämmelse

For detailed compliance information please select the desired article number.