

油面鏡 EH 22860.



產品描述

適合沒有過壓的油箱.

材質

密封環
• 抗油品

反射器
• 塑膠, 白色


環型螺帽
• 鋁

油面鏡
• 塑膠玻璃 (PMMA) - 透明的

組裝

在鑽孔中可不用裝置線 Ø H11. 透過簡單擰緊環形螺母來密封。

圖面

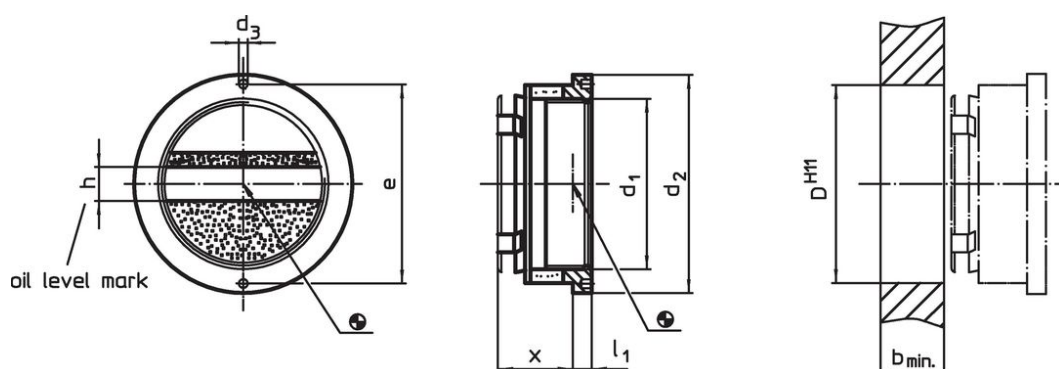


訂單資訊

尺寸								定位孔				品號
尺寸(視界開口) d ₁	d ₂	d ₃	x ~ [mm]	l ₁	b min	h	e	D H11 [mm]	min [°C]	max.	[g]	
無 油高標示												
16	25	2,2	15	3,5	9	–	21,0	20	-20	70	9,1	22860.0016
22	35	3,0	15	4,5	10	–	30,0	28	-20	70	18,0	22860.0022
32	45	3,0	18	5,5	12	–	40,0	38	-20	70	34,0	22860.0032
50	64	3,0	22	5,5	14	–	58,5	58	-20	70	87,0	22860.0050
有 油高標示												
16	25	2,2	15	3,5	9	5	21,0	20	-20	70	9,2	22860.0116
22	35	3,0	15	4,5	10	6	30,0	28	-20	70	18,0	22860.0122
32	45	3,0	18	5,5	12	8	40,0	38	-20	70	33,0	22860.0132
50	64	3,0	22	5,5	14	10	58,5	58	-20	70	85,0	22860.0150

配件

	尺寸(視界開口) d ₁	尺寸			品號
		d h9	e		
		[mm]			
組立工具					
	16	2,0	21,0	16	22860.0816
	22	2,8	30,0	30	22860.0822
	32	2,8	40,0	36	22860.0832
	50	2,8	58,5	49	22860.0850

應用範例

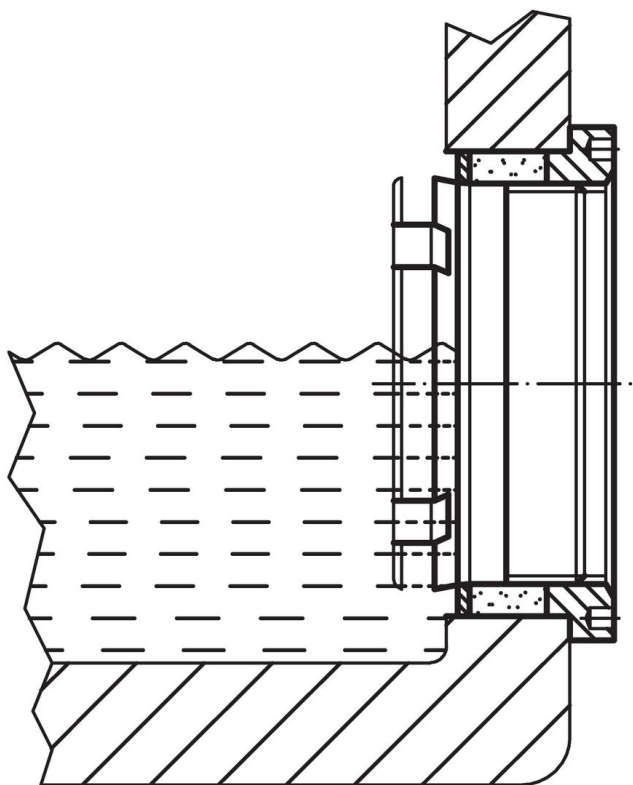

遵守

有關詳細的合規信息，請選擇所需的貨號。