

## Clamping Screws DIN 6332 • headless pin combined with different handles


EH 24890.

### CLAMPING SCREWS ACCORDING TO DIN - UPON REQUEST

#### PRODUCT DESCRIPTION

Clamping screws are manufactured to order. Single parts, however, are in stock.  
Description from order example only. No reference numbers.


#### DIMENSIONED DRAWING

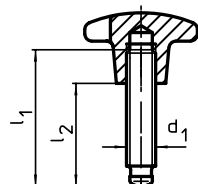

**Picture 1**


Clamping screw with

- palm grip DIN 6335 from cast iron or plastic
- star grip DIN 6336 from cast iron or plastic

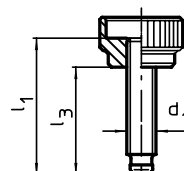

**Picture 2**


Clamping screw with  
knurled nut DIN 6303

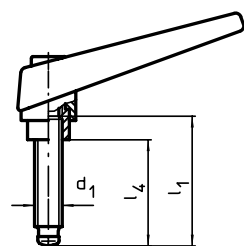

**Picture 3**

Clamping screw with

- clamping lever DIN 99
- adjustable clamping lever EH 24400.
- clamping lever EH 24430.
- clamping lever EH 24440.

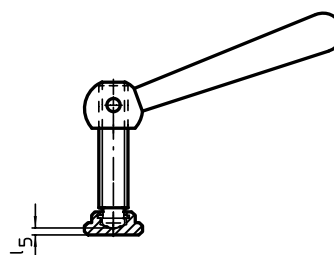

**Picture 4**

Clamping screw with  
thrust pad DIN 6311



## Clamping Screws DIN 6332 • headless pin combined with different handles

EH 24890.

## ORDER INFORMATION

| d <sub>1</sub> | l <sub>1</sub><br>DIN 6332<br>picture 1 | l <sub>2</sub><br>Nominal<br>thread<br>lengths<br>picture 1 | l <sub>3</sub><br>Nominal<br>thread<br>lengths<br>picture 2 | l <sub>4</sub><br>Nominal<br>thread<br>lengths<br>picture 3 | l <sub>5</sub><br>Nominal<br>thread<br>lengths<br>picture 4 |
|----------------|-----------------------------------------|-------------------------------------------------------------|-------------------------------------------------------------|-------------------------------------------------------------|-------------------------------------------------------------|
| M 8            | 40                                      | 27                                                          | 30                                                          | 28                                                          | 3,0                                                         |
| M 8            | 60                                      | 47                                                          | 50                                                          | 48                                                          | 3,0                                                         |
| M 10           | 60                                      | 44                                                          | 48                                                          | 45                                                          | 3,6                                                         |
| M 10           | 80                                      | 64                                                          | 68                                                          | 65                                                          | 3,6                                                         |
| M 12           | 60                                      | 40                                                          | 46                                                          | 41                                                          | 4,6                                                         |
| M 12           | 80                                      | 60                                                          | 66                                                          | 61                                                          | 4,6                                                         |
| M 12           | 100                                     | 80                                                          | 86                                                          | 81                                                          | 4,6                                                         |
| M 16           | 80                                      | 55                                                          | -                                                           | 55                                                          | 5,4                                                         |
| M 16           | 100                                     | 75                                                          | -                                                           | 75                                                          | 5,4                                                         |
| M 16           | 125                                     | 100                                                         | -                                                           | 100                                                         | 5,4                                                         |
| M 20           | 100                                     | -                                                           | -                                                           | 70                                                          | 5,5                                                         |
| M 20           | 125                                     | -                                                           | -                                                           | 95                                                          | 5,5                                                         |
| M 20           | 150                                     | -                                                           | -                                                           | 120                                                         | 5,5                                                         |

**Order example**

Clamping screw consisting of palm grip  
DIN 6336 GG and headless pin M 10 x 60 DIN 6332,  
without thrust pad DIN 6311

**Description**

Clamping screw M10 x 60 DIN 6332  
with DIN 6336 case iron without thrust pad

**Type**

Headless pin glued with handle part, DIN 99  
additionally pinned together.

Clamping screws available without or with thrust  
pad DIN 6311, please indicate in order.